



ACM Series


**PREMIUM WHOLE HOUSE AIR CLEANING SOLUTION
4" MEDIA AIR CLEANER**

FEATURES

- Slim profile for easy installation and easy stocking.
- Heavy-duty, 20 gauge galvanized steel cabinet construction – assembles using toggle locks.
- Factory-punched screw and drill-access holes in cabinet for fast and simple installation.
- Snap-on, ABS plastic cabinet door for easy filter replacement without tools.
- Private label program available

Model Number	CFM	Nominal Size	Cabinet Dimensions	Recommended CFM Range	Shipping Weight
ACM1000M-108	1000	16" x 20"	18 ¹ / ₈ " H x 19 ⁷ / ₈ " W x 5 ¹ / ₂ " D	600-1200	14 lbs.
ACM1400M-108	1400	16" x 25"	18 ¹ / ₈ " H x 24 ⁷ / ₈ " W x 5 ¹ / ₂ " D	1000-1600	15.75 lbs.
ACM1600M-108	1600	20" x 20"	22 ¹ / ₄ " H x 19 ⁷ / ₈ " W x 5 ¹ / ₂ " D	1200-1800	15 lbs.
ACM2000M-108	2000	20" x 25"	22 ¹ / ₄ " H x 24 ⁷ / ₈ " W x 5 ¹ / ₂ " D	1600-2200	17.25 lbs.

Each ACM includes a MERV 8 media filter.
Shipping specifications meets National Safety Transit Test (NSTT) standards.

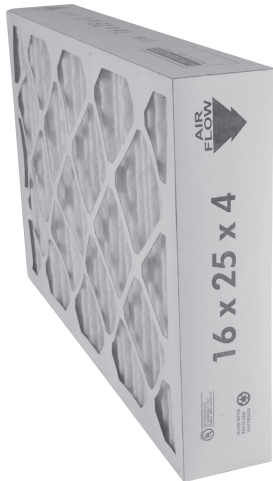

**FILTER REPLACEMENTS FOR 4" MEDIA
AIR CLEANERS**

FEATURES

- Available in MERV 8 and MERV 11 ratings.
- Includes installation arrow to indicate airflow direction.

STANDARD MERV 8 FILTER REPLACEMENT OR UPGRADE TO A PREMIUM MERV 11 FILTER

Model Number	Rating	CFM	Nominal Size	Actual Filter Size	Shipping Weight
FR1000M-108	MERV 8	1000	16" x 20" x 4"	15 ¹ / ₂ " H x 19 ¹ / ₂ " W x 3 ³ / ₄ " D	4.5 lbs.
FR1000M-111	MERV 11				6 lbs.
FR1400M-108	MERV 8	1400	16" x 25" x 4"	15 ¹ / ₂ " H x 19 ¹ / ₂ " W x 3 ³ / ₄ " D	6.25 lbs.
FR1400M-111	MERV 11				7 lbs.
FR1600M-108	MERV 8	1600	20" x 20" x 4"	19 ¹ / ₂ " H x 19 ¹ / ₂ " W x 3 ³ / ₄ " D	5.5 lbs.
FR1600M-111	MERV 11				6.25 lbs.
FR2000M-108	MERV 8	2000	20" x 25" x 4"	19 ¹ / ₂ " H x 24 ¹ / ₂ " W x 3 ³ / ₄ " D	7 lbs.
FR2000M-111	MERV 11				8 lbs.



FR1400-100

**FILTER REPLACEMENTS FOR 5" MEDIA
AIR CLEANERS**

FEATURES

- Four standard sizes.
- MERV 8 media.

REPLACEMENT MEDIA FILTERS

For Models	Model Number	CFM	Recommended CFM	A/C Tonnage	BTU Input Range
ACB1000-101	FR1000-100	1000	600-1200	up to 3.0	up to 120,000
ACB1400-101	FR1400-100	1400	1000-1600	up to 4.0	up to 160,000
ACB1600-101	FR1600-100	1600	1200-1800	up to 4.5	up to 180,000
ACB2000-101	FR2000-100	2000	1600-2200	up to 5.5	up to 220,000

INDOOR AIR QUALITY / ZONING SYSTEMS



UNIVERSAL MEDIA FILTER REPLACEMENTS

FR – FILTER REPLACEMENTS

Filter Model	CFM	Recommended CFM	A/C Tonnage	Input Range	MERV	Dimension
FR1400U-108	1400	1000-1600	up to 4.0	up to 160,000	8	20" x 24" x 4 ³ / ₈ "
FR2000U-108	2000	1600-2200	up to 5.5	up to 220,000	8	20" x 24 ¹ / ₂ " x 4 ³ / ₈ "

Nominal Size	CFM	Filter Manufacturer	Filter Model	Suggested Cabinet	MERV 8 Suggested Replacement
16" x 25" x 5"	1400	Aprilaire (Space-Gard)	401		FR1400U-108
16" x 25" x 5"	1400	Aprilaire (Space-Gard)		2400	FR1400U-108
16" x 25" x 5"	1400	Carrier	ACBCM1		FR1400U-108
16" x 25" x 5"	1400	Carrier		FILBBFTC0016	FR1400U-108
16" x 25" x 5"	1400	Carrier		FILCCFTC0016	FR1400U-108
16" x 25" x 5"	1400	Carrier		FILBBCAR0016	FR1400U-108
16" x 25" x 5"	1400	Carrier		FILCCCAR0016	FR1400U-108
16" x 25" x 5"	1400	Honeywell	FC100A1029		FR1400U-108
16" x 25" x 5"	1400	Honeywell	FC100C1009		FR1400U-108
16" x 25" x 5"	1400	Honeywell	FC200E1029		FR1400U-108
16" x 25" x 5"	1400	Honeywell		F100F2002	FR1400U-108
16" x 25" x 5"	1400	Honeywell		F100F1012	FR1400U-108
16" x 25" x 5"	1400	Honeywell		F100B1016	FR1400U-108
16" x 25" x 5"	1400	Honeywell		F150E1026	FR1400U-108
16" x 25" x 5"	1400	Honeywell		F200E1029	FR1400U-108
16" x 25" x 5"	1400	Lennox	X0582		FR1400U-108
16" x 25" x 5"	1400	Lennox	X0583		FR1400U-108
16" x 25" x 5"	1400	Lennox	X0584		FR1400U-108
16" x 25" x 5"	1400	Lennox		BMAC-14C	FR1400U-108
16" x 25" x 5"	1400	Trion	255649-102		FR1400U-108
16" x 25" x 5"	1400	Trion		455602-119	FR1400U-108
16" x 25" x 5"	1400	White-Rodgers	FR1400U-108		FR1400U-108
16" x 25" x 5"	1400	White-Rodgers		ACM1400U-108	FR1400U-108
16" x 25" x 5"	1400	White-Rodgers	FR1400-100		FR1400U-108
16" x 25" x 5"	1400	White-Rodgers		ACM1400-101	FR1400U-108
16" x 25" x 5"	1400	White-Rodgers		ACB1400-101	FR1400U-108
20" x 25" x 5"	2000	Aprilaire (Space-Gard)	201		FR2000U-108
20" x 25" x 5"	2000	Aprilaire (Space-Gard)		2250	FR2000U-108
20" x 25" x 5"	2000	Carrier	ACBCM2		FR2000U-108
20" x 25" x 5"	2000	Carrier		FILBBFTC0020	FR2000U-108
20" x 25" x 5"	2000	Carrier		FILBBCAR0020	FR2000U-108
20" x 25" x 5"	2000	Carrier		FILCCFTC0020	FR2000U-108
20" x 25" x 5"	2000	Carrier		FILCCCAR0020	FR2000U-108
20" x 25" x 5"	2000	Honeywell	FC100A1037		FR2000U-108
20" x 25" x 5"	2000	Honeywell	FC200E1037		FR2000U-108
20" x 25" x 5"	2000	Honeywell		F100F2010	FR2000U-108
20" x 25" x 5"	2000	Honeywell		F100F1038	FR2000U-108
20" x 25" x 5"	2000	Honeywell		F100B1024	FR2000U-108
20" x 25" x 5"	2000	Honeywell		F150E1034	FR2000U-108
20" x 25" x 5"	2000	Honeywell		F200E1037	FR2000U-108
20" x 25" x 5"	2000	Lennox	X0586		FR2000U-108
20" x 25" x 5"	2000	Lennox	X0587		FR2000U-108
20" x 25" x 5"	2000	Lennox		BMAC-20C	FR2000U-108
20" x 25" x 5"	2000	Trion	255649-102		FR2000U-108
20" x 25" x 5"	2000	Trion		455602-019	FR2000U-108
20" x 25" x 5"	2000	White-Rodgers	FR2000U-108		FR2000U-108
20" x 25" x 5"	2000	White-Rodgers	FR2000U-110		FR2000U-108
20" x 25" x 5"	2000	White-Rodgers		ACM2000U-108	FR2000U-108
20" x 25" x 5"	2000	White-Rodgers		ACM2000U-110	FR2000U-108
20" x 25" x 5"	2000	White-Rodgers	FR2000-100		FR2000U-108
20" x 25" x 5"	2000	White-Rodgers		ACM2000-101	FR2000U-108
20" x 25" x 5"	2000	White-Rodgers		ACB2000-101	FR2000U-108